

U.I. Lapp GmbH	<b>DATASHEET</b>	
	<b>Marking rings PC 40</b>	61822560 14.11.2013

Open marking rings with pre-printed characters and numbers for marking wires/single cores after assembly, Snap-On mechanism, flame-retardant according to UL 94 V0



Heat-resistant



UV-resistant

### Application range

For Single core marking

Marking after assembly

Also possible to use for marking wires before assembly

### Benefits

Open marking rings with pre-printed number or character

The shape ensures secure fixation to the cable, while the anti-rotation feature allows for a secure combination marking.

Resistant to UV radiation, corresponding to 1 year outdoor in the south of Sweden

Easy mounting through clipping

### Product features

Extremely flame-retardant according to UL 94 V0

### Remark


Photographs are not to scale and do not represent detailed images of the respective products.


Contents: roll, metre, unit, marker, label

### Technical Data

Article designation:	PC 40 / F
Width x height (mm):	6,9 x 6,7
Sleeve length (mm):	4
Area of application Ø (mm):	5 - 6,2
Contents (unit):	200
Colour delivered:	yellow
Material:	Cadmium-free and silicon-free hard PVC
Temperature range:	-30°C to +60°C

Product Management	Document: Marking rings PC 40	1 / 2
--------------------	-------------------------------	-------

U.I. Lapp GmbH	<b>DATASHEET</b>	 <b>LAPP GROUP</b>
	<b>Marking rings PC 40</b>	<b>61822560</b> <b>14.11.2013</b>

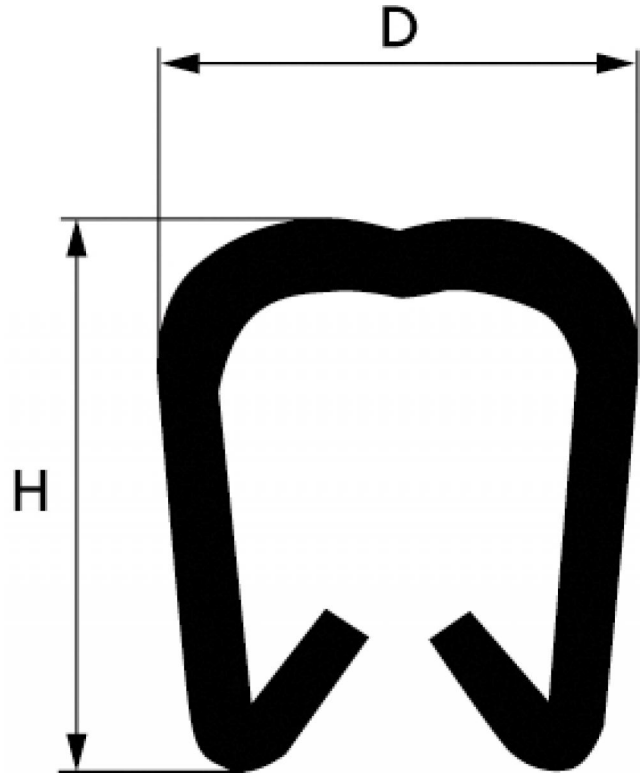

Product Management	Document: Marking rings PC 40	2 / 2
--------------------	-------------------------------	-------